

Power Supplies

Reliable DC power for your panel



Quick Link
P222

S8VS - Single Phase

Compact power supplies with optional Smart Display models

- Unique LED display and alarm output shorten troubleshooting and support preventive maintenance (60-480 W models)
- Power supply service life monitor ("A" type)
- Run-time monitor for connected load ("B" type)
- Power Factor Correction function standard
- Class 2 output (90 W models and below)
- Alarm outputs (90 - 480 W LED models) available: 1 undervoltage outputs, 1 for lifetime or run-time
- 3-year warranty on all models

Enclosure

- Covered

Terminal Block Form

- Screw and cage clamp terminals

Approvals

- Meets international safety standards: UL, cUL, UL508 Listed, SEMI F47 and CE



Quick Link
P224

S8VM - Single Phase

Compact power supplies with optional LED diagnostic display

- Slim designs help downsize machine panels
- Overvoltage protection (standard) of 105% to 160% rated load current
- Undervoltage alarm option signals an error and helps identify the source
- Terminal block protects fingers against electric shock
- Multiple mounting options
- Class 1, Div 2 rated for hazardous areas
- Power Factor Correction function standard
- 1-year warranty

Enclosure

- Open-frame and Covered

Terminal Block Form

- Screw terminals

Approvals

- cULus Listed, cULus Recognized, TUV, and CE



Quick Link
P229

S8VE - Single Phase

Compact power supply (without indication monitor)

- Universal input voltage
- Compact size saves panel space and fits between shorter ducts
- Easy to install screwless terminal block models available
- 2-year warranty

Enclosure

- Covered

Terminal Block Form

- Screw and cage clamp terminals

Approvals

- cULus Listed, cULus Recognized, VDE, CE, and SEMI F47



Quick Link
P228

S8JX - Single Phase

Cost effective power supplies with multiple mounting options

- Universal input voltage
- Multiple mounting options
- Series operation: connect up to 2
- Parallel operation on 300 and 600 W
- Built-in overload and overvoltage protection
- Adjustable voltage output (-10% to 15%)
- 2-year warranty

Enclosure

- Open-frame and Covered

Terminal Block Form

- Screw and cage clamp terminals

Approvals

- cULus Listed, cULus Recognized, VDE, CE, and SEMI F47



Quick Link
P226

S8VT-F - Three Phase

Compact three-phase power supply

- Three-phase input voltage
- High stability, low ripple and noise level
- Conforms to EN61000-3-2
- Efficiency: 86% to 91% (varies per model)
- Compact design and convection air cooled (no fans)
- Overload and overvoltage protection included
- Parallel and series operation possible
- 1-year warranty

Enclosure

- Covered

Terminal Block Form

- Screw terminals


Approvals

- cULus Listed, cULus Recognized, VDE, CE, and SEMI F47

Power Supplies

Find the right power rating to keep your critical equipment operational

Power Rating Line-up

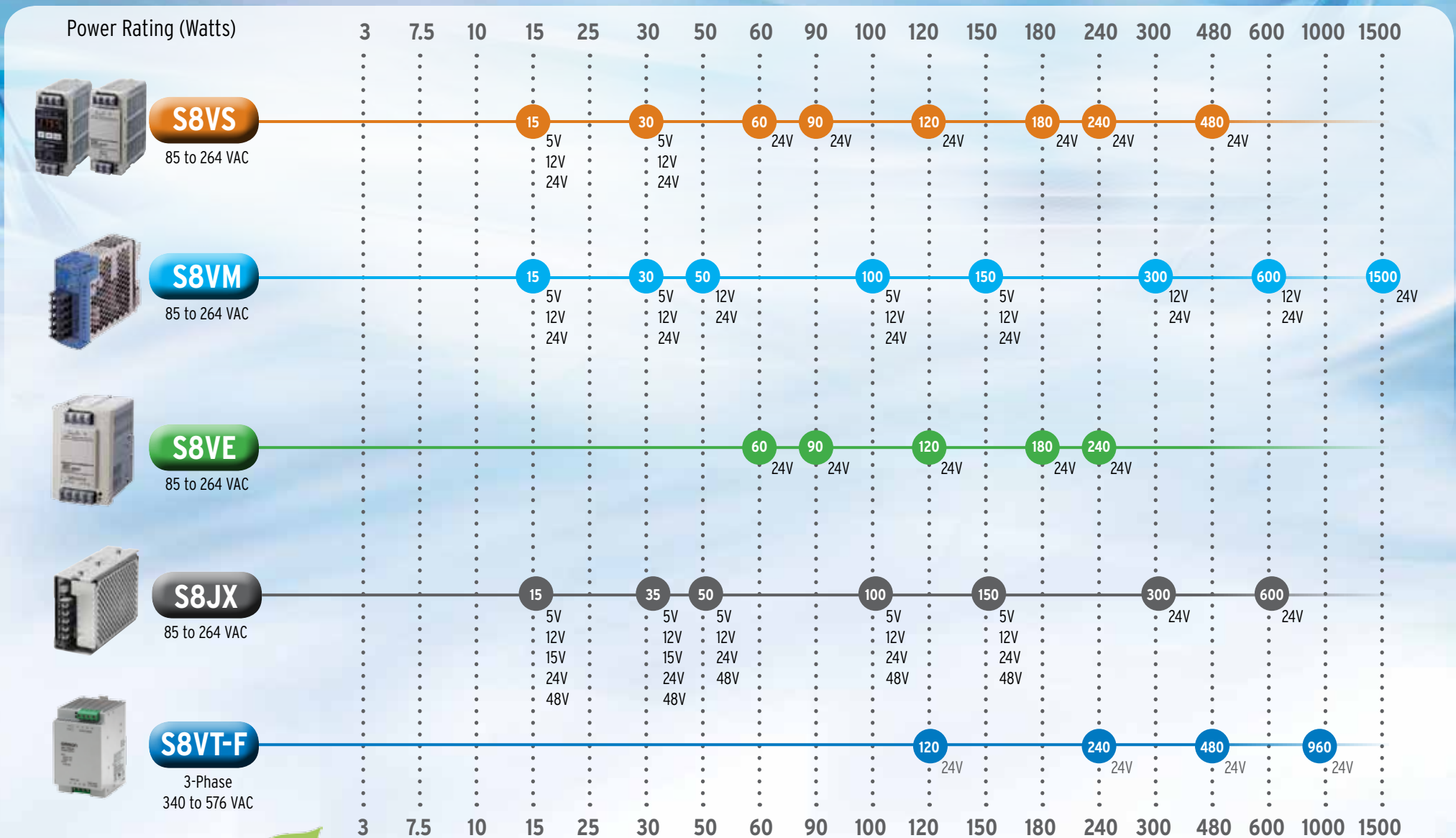

All of Omron's
Power Supplies are
RoHS Compliant